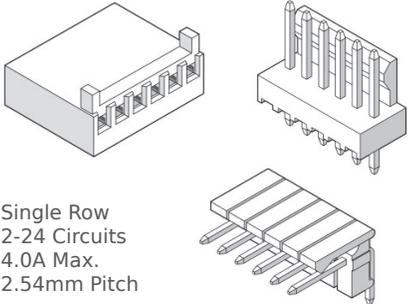
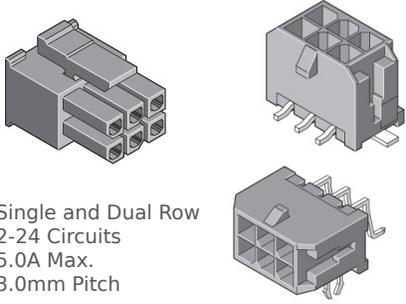
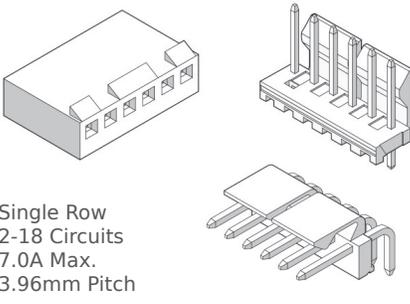
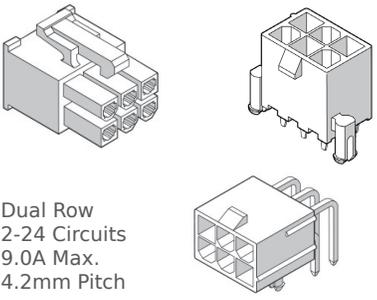
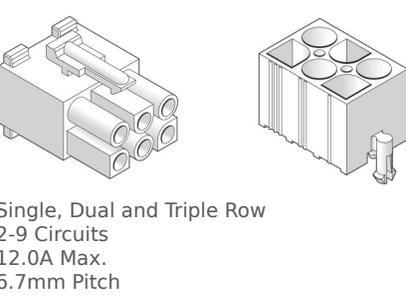
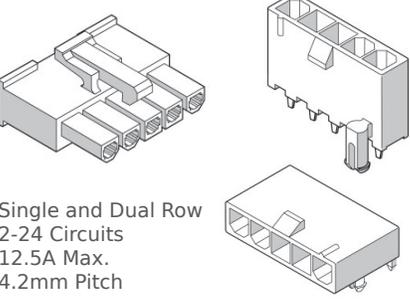
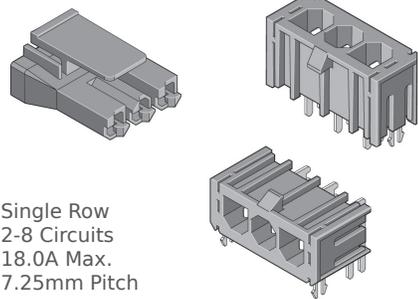
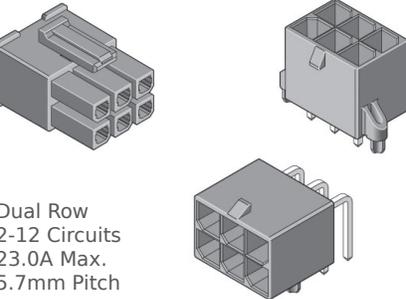
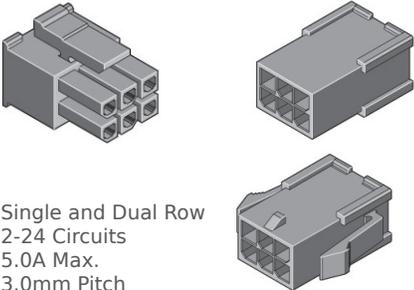
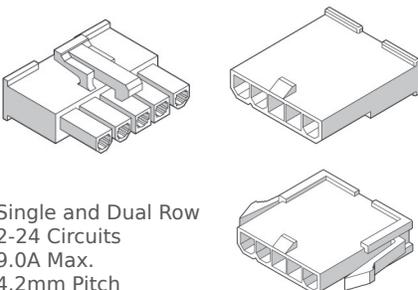
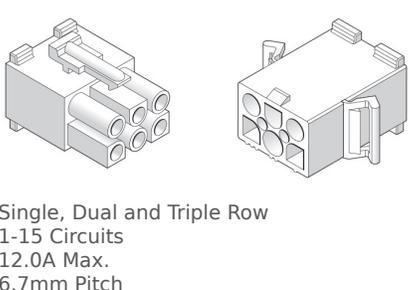
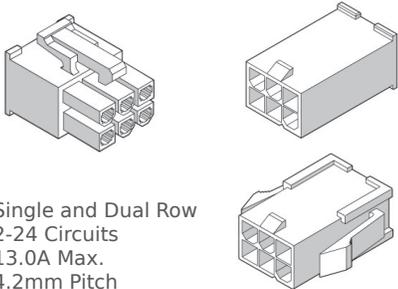
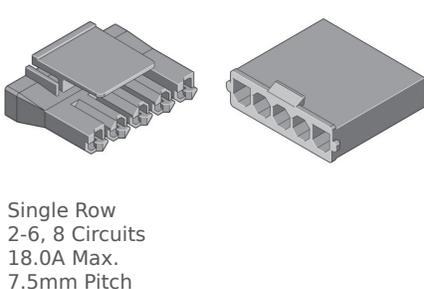





Wire-to-Board

KK® 254	Micro-Fit 3.0™	KK® 396
 <p>Single Row 2-24 Circuits 4.0A Max. 2.54mm Pitch</p>	 <p>Single and Dual Row 2-24 Circuits 5.0A Max. 3.0mm Pitch</p>	 <p>Single Row 2-18 Circuits 7.0A Max. 3.96mm Pitch</p>
Mini-Fit® Jr.™	.093" Pin and Socket	Mini-Fit® Plus
 <p>Dual Row 2-24 Circuits 9.0A Max. 4.2mm Pitch</p>	 <p>Single, Dual and Triple Row 2-9 Circuits 12.0A Max. 6.7mm Pitch</p>	 <p>Single and Dual Row 2-24 Circuits 12.5A Max. 4.2mm Pitch</p>
Sabre™	Mega-Fit	
 <p>Single Row 2-8 Circuits 18.0A Max. 7.25mm Pitch</p>	 <p>Dual Row 2-12 Circuits 23.0A Max. 5.7mm Pitch</p>	




Wire-to-Wire / Wire-to-Panel

Micro-Fit 3.0™	Mini-Fit Jr.™	.093" Pin and Socket
 <p>Single and Dual Row 2-24 Circuits 5.0A Max. 3.0mm Pitch</p>	 <p>Single and Dual Row 2-24 Circuits 9.0A Max. 4.2mm Pitch</p>	 <p>Single, Dual and Triple Row 1-15 Circuits 12.0A Max. 6.7mm Pitch</p>
Mini-Fit® Plus	Sabre™	
 <p>Single and Dual Row 2-24 Circuits 13.0A Max. 4.2mm Pitch</p>	 <p>Single Row 2-6, 8 Circuits 18.0A Max. 7.5mm Pitch</p>	


Panel-to-Panel (Blindmating)

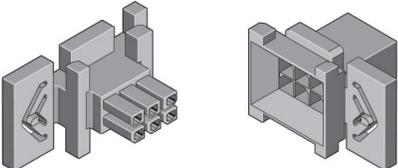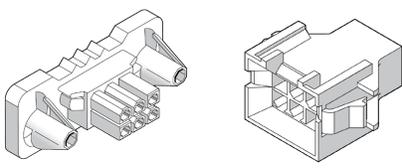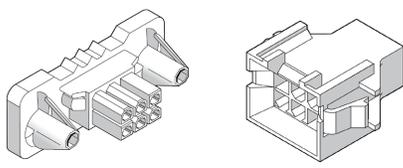Micro-Fit BMI™	Mini-Fit® BMI	Mini-Fit® Plus (Blindmating)
 <p>Dual Row 4-24 Circuits 5.0A Max. 3.0mm Pitch</p>	 <p>Dual Row 4-24 Circuits 8.0A Max. 4.2mm Pitch</p>	 <p>Dual Row 4-24 Circuits 12.0A Max. 4.2mm Pitch</p>

Panel-to-Board (Blindmating)

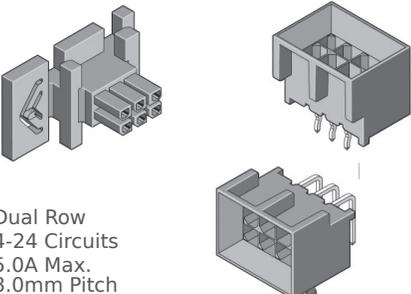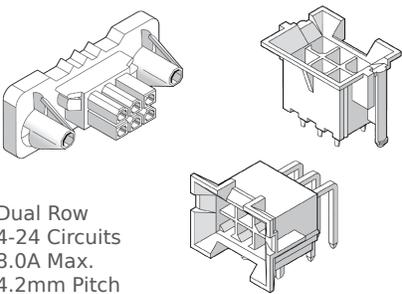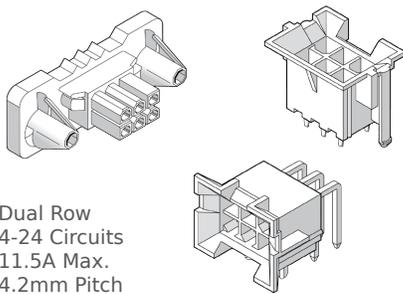Micro-Fit BMI™	Mini-Fit® BMI	Mini-Fit® Plus (Blindmating)
 <p>Dual Row 4-24 Circuits 5.0A Max. 3.0mm Pitch</p>	 <p>Dual Row 4-24 Circuits 8.0A Max. 4.2mm Pitch</p>	 <p>Dual Row 4-24 Circuits 11.5A Max. 4.2mm Pitch</p>

Board-to-Board

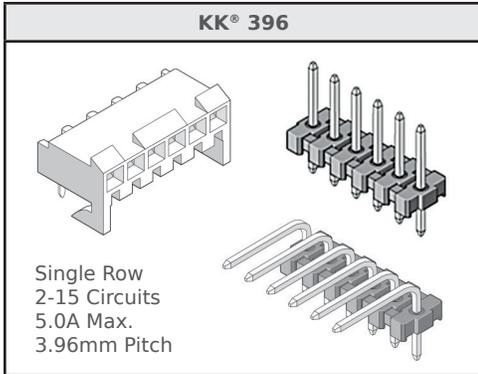

Board-to-Board (Blindmating)

Micro-Fit BMI™	Mini-Fit® BMI.	Mini-Fit® Plus (Blindmating)
<p>Dual Row 4-24 Circuits 5.0A Max. 3.00mm Pitch</p>	<p>Dual Row 4-24 Circuits 8.0A Max. 4.2mm Pitch</p>	<p>Dual Row 4-24 Circuits 11.0A Max. 4.2mm Pitch</p>

		KK® 254	Micro-Fit 3.0™	KK® 396	.093"	Mini-Fit®	Sabre™	Mega-Fit
PCB Processing	Wave Solder	X	X	X	X	X	X	X
	Reflow 260°C Max.	X	X	X		X	X	X
	Press-fit		X			X		
Flammability	Glow Wire (IEC 60335-1)		X			X	X	X
	UL 94 V-0	X	X	X	X	X	X	X
	UL 94 V-2	X	X	X	X	X	X	
Options	Positive Locking		X		X	X	X	X
	Blindmating		X			X		
	Low-halogen		X			X	X	
	High Mating Cycles					X		
	Terminal Position Assurance (TPA)					X		
Headers, Receptacles, Plugs	Plug		X		X	X	X	
	Panel Mount Plug		X		X	X		
	Receptacle	X	X	X	X	X	X	X
	Bottom Entry PCB Receptacle	X		X				
	Right Angle Entry PCB Receptacle	X		X				
	Top Entry PCB Receptacle	X	X	X		X		
	Vertical Header	X	X	X	X	X	X	X
	Right Angle Header	X	X	X		X	X	X
Plating	Tin	X	X	X	X	X	X	X
	Gold	X	X	X	X	X		X

Note: Some attributes may not be available in all configurations of a specific product family.